


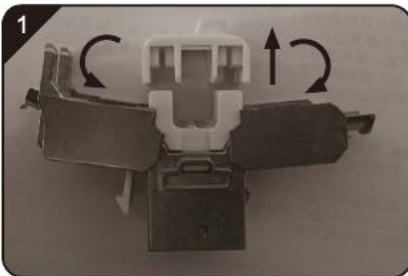



# Installation Guide

WireNET Shielded Keystone toolless CAT5e, CAT6 & CAT 6A Jack instruction


Partnumber	Description	Front view
CU-JS5ME	WireNET® Shielded Modular Jack, <u>KeyConnect</u> CAT5E	
CU-JS6ME	WireNET® Shielded Modular Jack, <u>KeyConnect</u> CAT6	
CU-JS6ME	WireNET® Shielded Modular Jack, <u>KeyConnect</u> CAT6A	

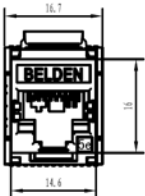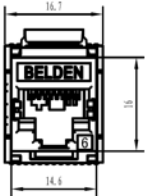

1 Open the product and remove the module cable pressure cover.

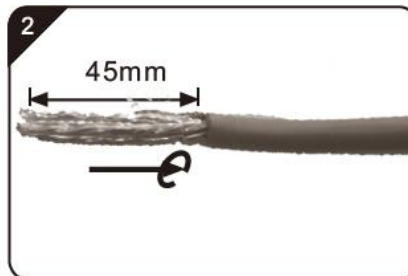


2 Stripped skin to 45MM and then sort shield braid.

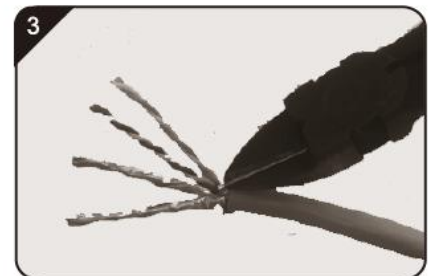


3 Put the cable through pressure cover and then cut the foil.




4 Note: the white line pairs with the color line  
Refer to color and then put the cable into the pressure cap, and cut off the needless cable edge.

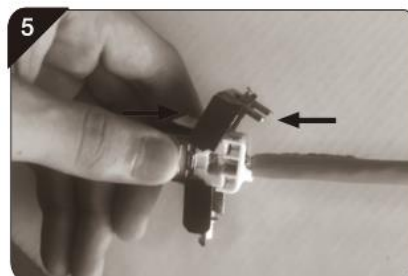


5 put the cable pressing cover into module line base (with a little strength) then use the both side cover to grip

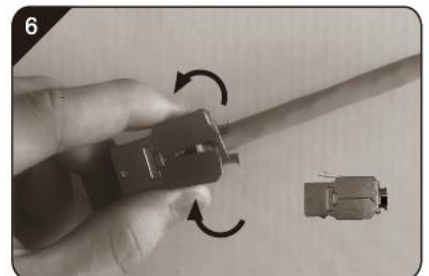

6 grip the right stress area in black.

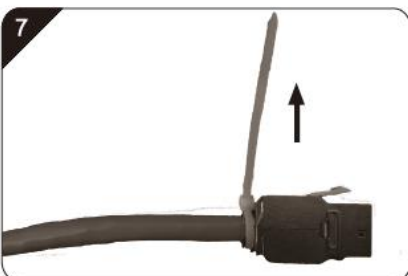

7 Push the cable tie in and lock it

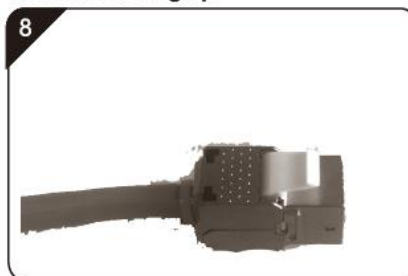

8 Complete.