
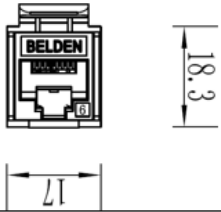
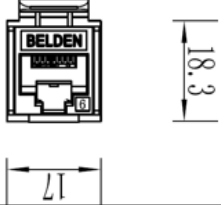


# Installation Guide

## WireNET UTP Keystone CAT 6 Jack instruction


Partnumber	Color	Description	Front view
CU-JU6EW	White	<u>WireNET®</u> UTP Modular Jack, <u>KeyConnect</u> CAT6	
CU-JU6BK	Black	<u>WireNET®</u> UTP Modular Jack, <u>KeyConnect</u> CAT6	

JACK PIN DESIGNATIONS	TIA / EIA T568A	TIA / EIA T568B
	1	White/Green
2	Green	Orange
3	White/Orange	White/Green
6	Orange	Green
4	Blue	Blue
5	White/Blue	White/Blue
7	White/Brown	White/Brown
8	Brown	Brown

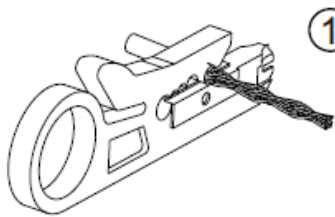


① Strip back cable Jacket using Coaxial cable tool or equivalent.

strip 2" of cable jacket and position first pair according to color code. The center channel lets you preserve wire twisting to well within 0.5" of the termination point.

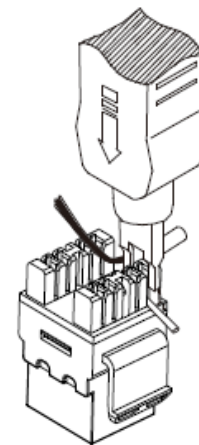

②

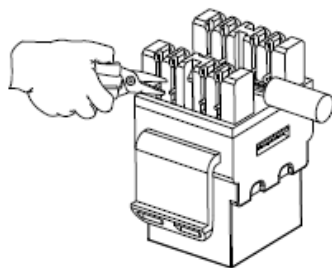

③ As with the first pair, position and terminate each subsequent pair one at a time until termination is complete.

Place strain relief cap. the jack is now ready to be snapped into faceplate or mounting box.

④

